


13105-009 PSU 19" AC/DC LINEAR REGULATOR, SINGLE, PSM 124

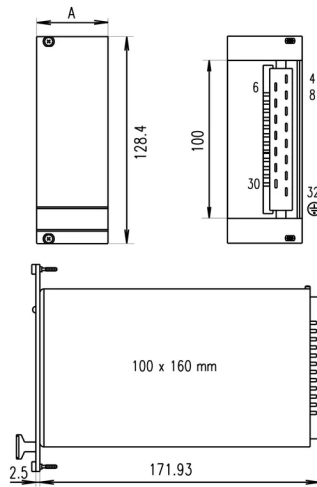

KEY FEATURES

1 output voltage

High control accuracy, low residual ripple and low interference

Mains/line voltage 230 VAC (can be switched to 115 VAC with mains/line voltage conversion kit)

Suited for medical applications (8 mm safety clearances)

PRODUCT ATTRIBUTES

Product Type: Power Supply

Type: 19" Linear Regulator

Input Voltage AC: 230 V

Power: 36 W

Number of Output Voltages: 1

Voltage 1: 24 V

Current 1: 1.5 A

Rack Height: 3 U

Rack Width: 10 HP

Depth: 171.93 mm

ADDITIONAL PRODUCT DETAILS

Linear regulator for applications requiring very low output noise level.

Please order Front Panel separately.

Output Data at Ta= 0 ... 50 °C.

CERTIFICATIONS



North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**

© 2024 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.