


**21101-909 COLLAR SCREW, KNURLED HEAD LONG VERSION, M2.5 X 12.3 MM, BRASS NICKEL PLATED; 100 PIECES**

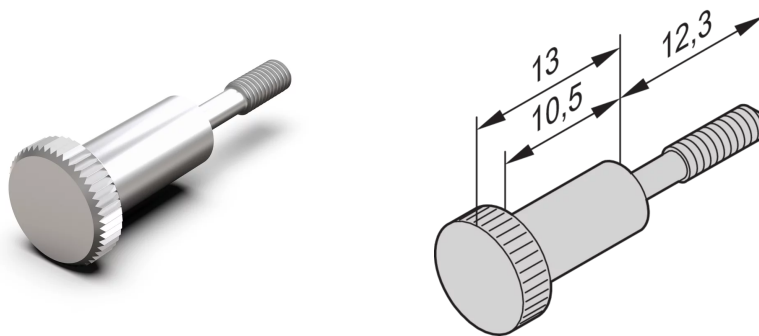

**KEY FEATURES**

Collar Screw, Knurled Head Long Version

**PRODUCT ATTRIBUTES**

Product Type: Screw

Type: Screw

Works With: Front Panels

Package Quantity: 100

Thread Size: M2.5

Length: 12.3 mm

Material: Brass

Finish: Nickel Plated

Depth: 25.3 mm

Height: 8 mm

Torque: 0.3 N·m

Width: 8 mm

**ADDITIONAL PRODUCT DETAILS**

Used with horizontal rails with long lip (H-LD and R-LD)



**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[schroff.nvent.com](https://schroff.nvent.com)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[schroff.nvent.com](https://schroff.nvent.com)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[schroff.nvent.com](https://schroff.nvent.com)

**Middle East & India**

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[schroff.nvent.com](https://schroff.nvent.com)



Our powerful portfolio of brands:  
[nVent.com](https://nVent.com) **CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**