


Date : 5 Nov 19
Version : V1

1-Phase 230V 16A switched PDU + outlet measurement PDU drawing & specification


RP3000: Outlet Measurement, Outlet Switch ON / OFF, SNMP Hardware

RackPower

 
Front view :



Top View :

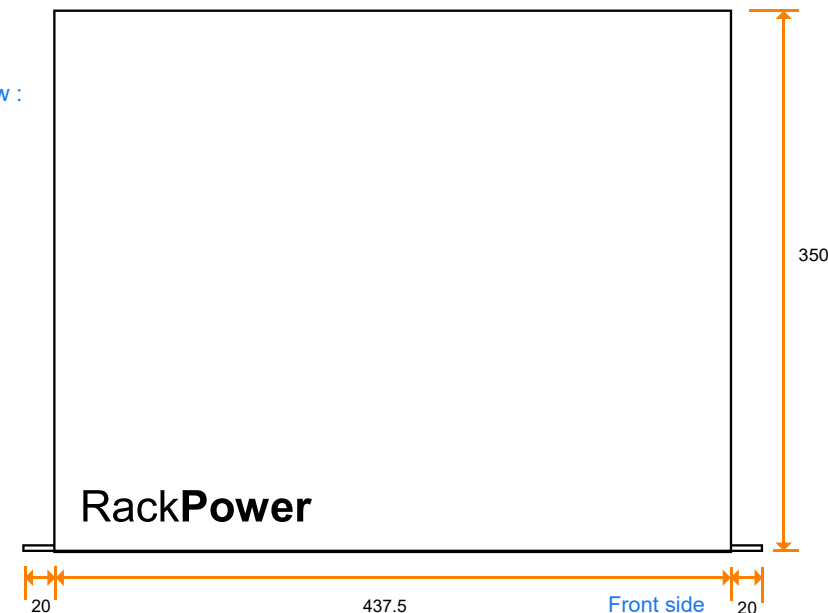

Rear view :

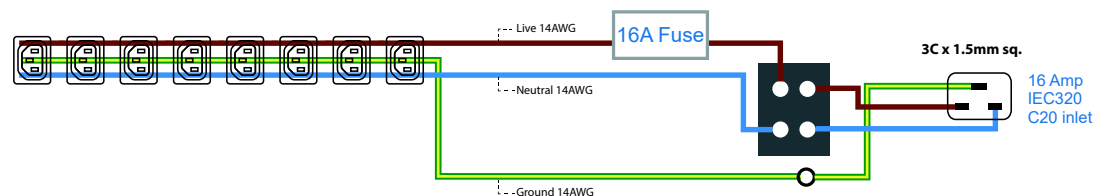

Item Number
60110-461

unit : mm

Single phase switched + outlet measurement PDU

Input Rating : 16A, 230V
Outlet : 10A Rated C13 x 8
Inlet : 16A IEC320 C20 inlet
Cordset : NIL
Protection : 16A resettable fuse x 1
Circuit Details : Output 16A max. C 13 # 1 - 8

Meter Features (WSi Switched PDU + Outlet Measurement)

Local Display : Field replaceable 2.0" color LCD with touchscreen
Bank Measurement : Current (A), Energy (kWh), Voltage (V) & Power factor
Outlet Measurement : Current (A), Energy (kWh)
Outlet Control : Outlet Switch ON / OFF
Accuracy : $\pm 1\%$ Billing-grade
IP Access : via IP dongle, one IP Access up to 16 PDU Levels
Cascade : Up to 16 PDU under single IP address via IP dongle
SNMP : V2 / V3 via IP dongle
Sensor Port x 2 : Temp. Sensor / Temp. + Humid. Sensor

EMC Compliance : FCC & CE certified
Safety Compliance : CE / LVD certified
Environment Compliance : RoHS2 & REACH

Operating Temperature : -5 to 60 °C
Storage Temperature : -25 to 65 °C
Operating Altitude : 0 to 2,000 m
Storage Altitude : 0 to 15,000 m
Humidity : 8 to 95% RH, non-condensing

Chassis Material : Steel
Chassis Color : Black

Product Dimension : 437.5 (W) x 350 (D) x 44.5 (H) mm
Net Weight : 4.56 kg

Packing dimension : 550 (W) x 550 (D) x 160 (H) mm
PDU gross weight : 4.82 kg