

 


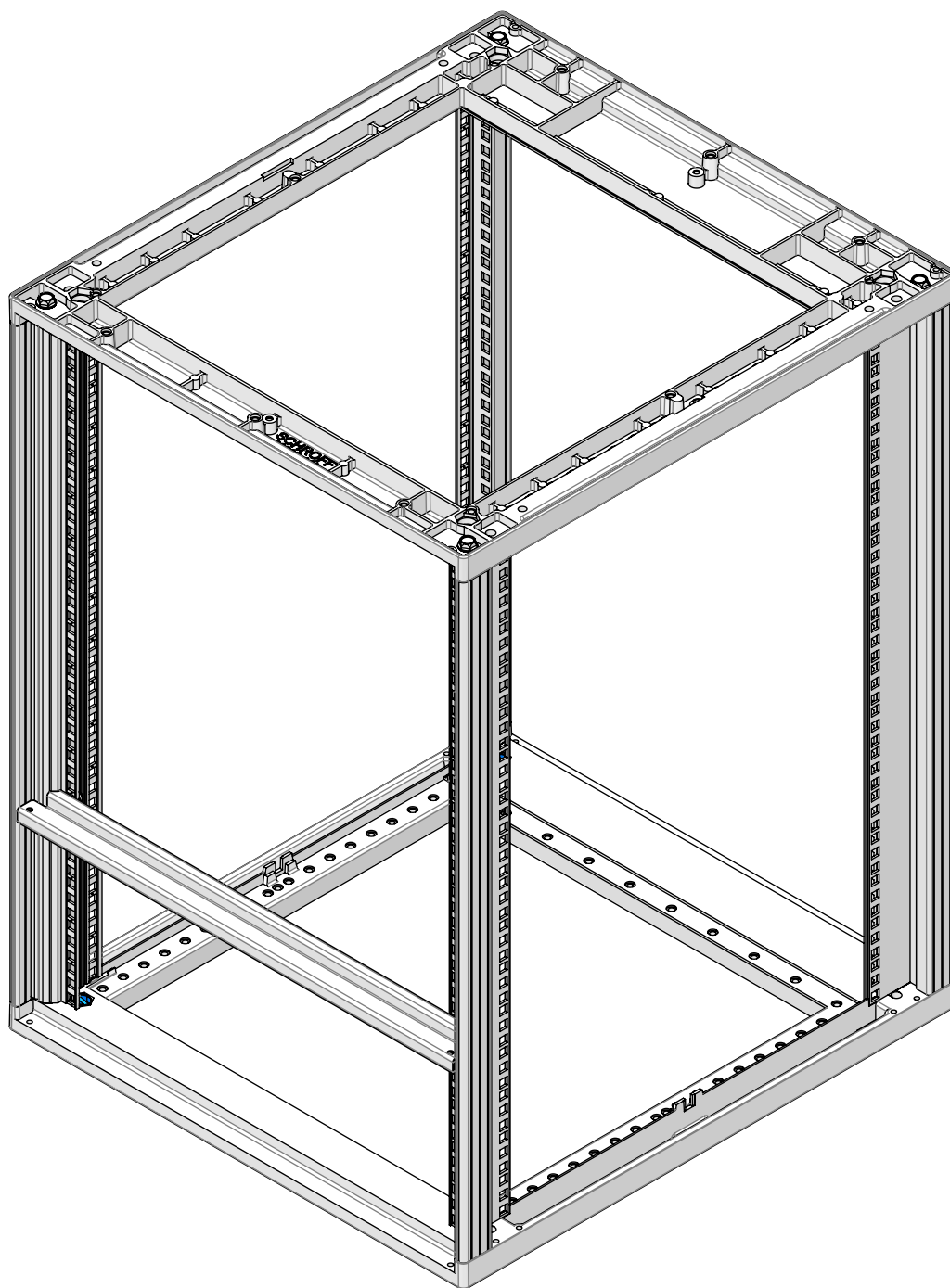


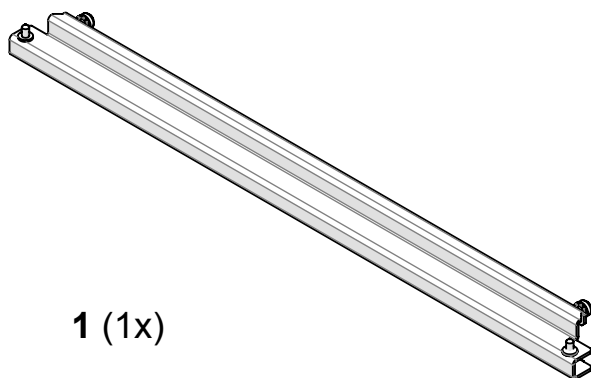

1 (1x)



2 (2x)

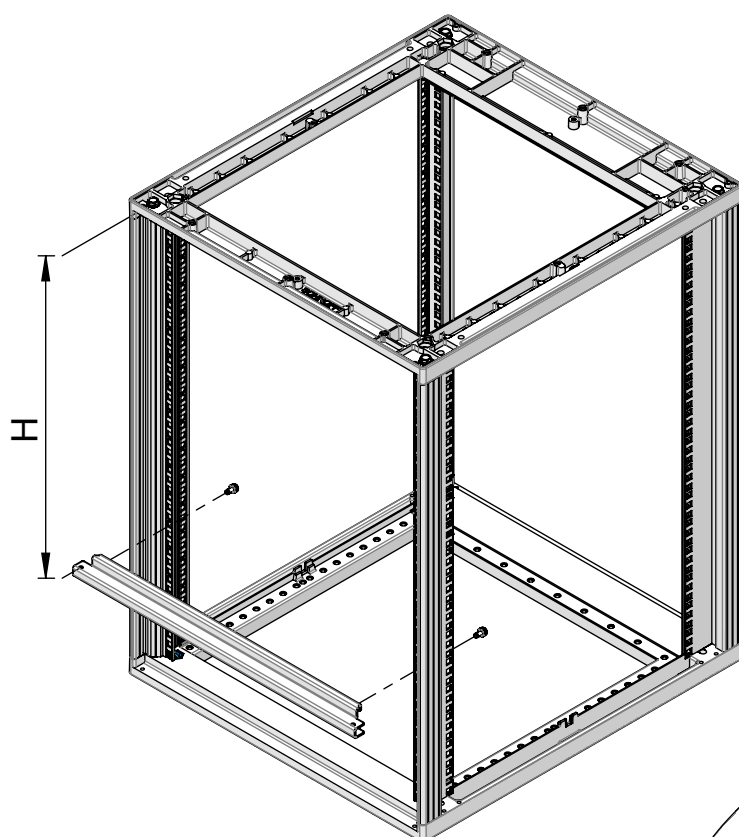

U	H ~ (mm)
6U	495,1
9U	414,5
12U	761,8
16U	939,6
20U	1117,4
25U	1339,6
29U	1517,4
34U	1739,7
38U	1917,5
43U	2139,7
47U	2317,5

