


13100-122 PSU 19" AC/DC MAXPOWER 100 W, TRIPLE, MAX 312

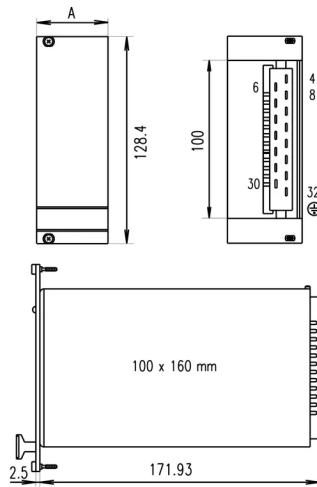

KEY FEATURES

Wide input voltage range 90 ... 254 V AC and 100 ... 360 VDC with active power-factor correction (PFC)

3 output voltages

Signalling: Output voltage OK

High power density

PRODUCT ATTRIBUTES

Product Type: Power Supply

Type: 19" Switched-Mode

Input Voltage AC: 90 – 264 V

Power: 100 W

Number of Output Voltages: 3

Voltage 1: 5 V

Current 1: 8 A

Voltage 2: 12 V

Current 2: 2.5 A

Voltage 3: 12 V

Current 3: 2.5 A

Rack Height: 3 U

Rack Width: 8 HP

Depth: 171.93 mm

ADDITIONAL PRODUCT DETAILS

Pluggable 19" Power Supplies with H15 connector for fanless applications. With wide range AC input and three output voltages.

Please order front panel separately.

Output data at mains voltage > 190 VAC, Ta = -25 ... 50 °C.

CERTIFICATIONS



North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**

© 2024 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.