


## 13105-029 PSU 19" AC/DC LINEAR REGULATOR, DUAL, PSG 224

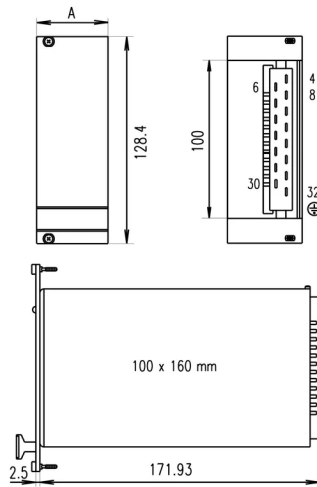

### KEY FEATURES

2 output voltages, galvanically separated

High control accuracy, low residual ripple and very low interference

Mains/line voltage 230 VAC (can be switched to 115 VAC with mains/line voltage conversion kit)

Suited for medical applications (8 mm safety clearances)

### PRODUCT ATTRIBUTES

Product Type: Power Supply

Type: 19" Linear Regulator

Input Voltage AC: 230 V

Power: 58 W

Number of Output Voltages: 2

Voltage 1: 24 V

Current 1: 1.2 A

Voltage 2: 24 V

Current 2: 1.2 A

Rack Height: 3 U

Rack Width: 14 HP

Depth: 171.93 mm

## ADDITIONAL PRODUCT DETAILS

---

Linear regulator for application which only allows a very low noise level at the outputs.

Please order Front Panel separately.

Output Data at Ta= 0 ... 50 °C.

## CERTIFICATIONS

---

**ROHS**  
COMPLIANT

**CE**

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[schroff.nvent.com](https://schroff.nvent.com)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[schroff.nvent.com](https://schroff.nvent.com)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[schroff.nvent.com](https://schroff.nvent.com)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[schroff.nvent.com](https://schroff.nvent.com)



Our powerful portfolio of brands:  
**nVent.com** CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2024 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.