
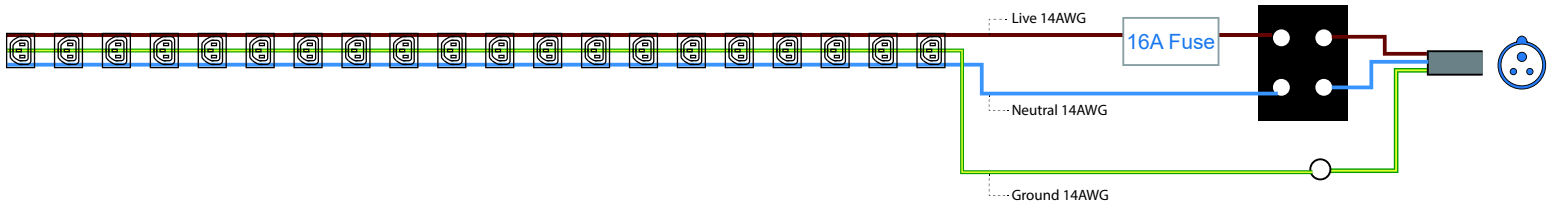


1-Phase 230V 16A switched PDU drawing & specification

RP2000: Strip level measurement, Outlet Switch ON / OFF, SNMP Hardware

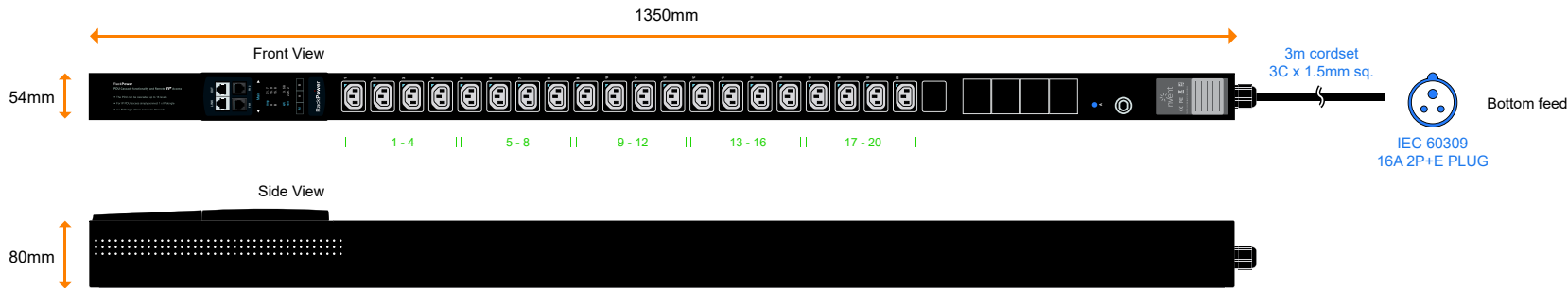

Item Number
60110-464

Single phase switched PDU

- Input Rating : 16A, 230V
- Outlet : 10A Rated C13 x 20
- Inlet : 16A IEC60309 2P+E plug
- Cordset : 3 meter 1.5mm sq. H05V V-F cordset
- Protection : 16A resettable fuse x 1
- Circuit Details : Output 16A max. C 13 # 1 - 20

Meter Features (WS Switched PDU)

- Local Display : Field replaceable 2.8" color LCD with touchscreen
- Bank Measurement : Current (A), Energy (kWh), Voltage (V) & Power factor
- Outlet Control : Outlet Switch ON / OFF
- Accuracy : ±1% Billing-grade
- IP Access : via IP dongle, one IP Access up to 16 PDU Levels
- Cascade : Up to 16 PDU under single IP address via IP dongle
- SNMP : V2 / V3 via IP dongle
- Sensor Port x 2 : Temp. Sensor / Temp. + Humid. Sensor

- EMC Compliance : CE / EMC certified
- Safety Compliance : CE / LVD certified
- Environment Compliance : RoHS2 & REACH
- Operating Temperature : -5 to 60 °C
- Storage Temperature : -25 to 65 °C
- Operating Altitude : 0 to 2,000 m
- Storage Altitude : 0 to 15,000 m
- Humidity : 8 to 95% RH, non-condensing
- Chassis Material : Steel
- Chassis Color : Black

- Product Dimension : 2.1 (W) x 3.1 (D) x 53.1 (H) inch
- Net Weight : 14.33 lbs

- Packing dimension (for 2 PDUs) : 4.3 (W) x 10.6 (D) x 80.4 (H) inch
- PDU gross weight (for 2 PDUs) : 35.77 lb