



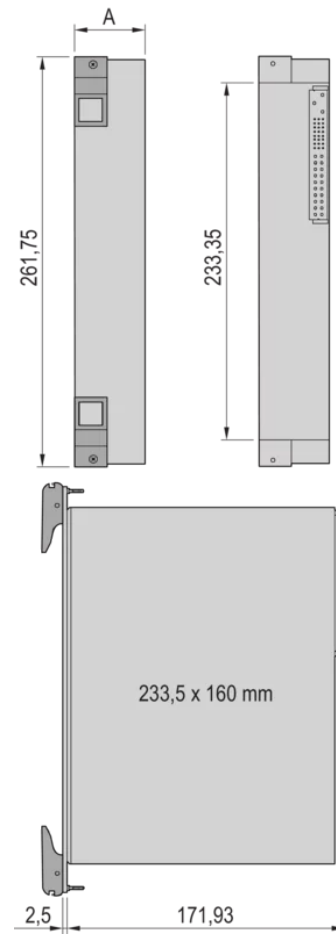

SCHROFF

13100-145 PSU 19" FOR COMPACTPCI, AC/DC, 6 U, 8 HP

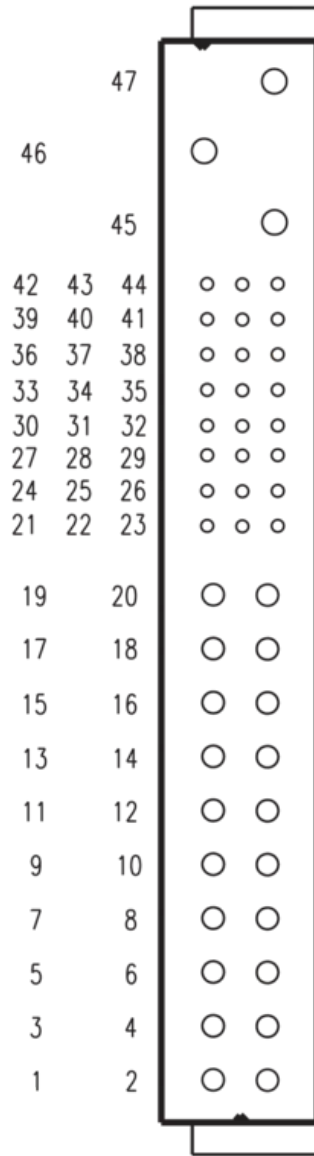

## KEY FEATURES

Connector P47 and CompactPCI signalling

4 output voltages

Redundant operation with Current Share Bus (CSB), hot-swap

## PRODUCT ATTRIBUTES

---

Product Type: Power Supply

Type: 19" Switched-Mode

Works With: CompactPCI and VME64x

Input Voltage AC: 90 – 264 V

Power: 500 W

Number of Output Voltages: 4

Voltage 1: 5 V

Current 1: 50 A

Voltage 2: 3.3 V

Current 2: 60 A

Voltage 3: 12 V

Current 3: 12 A

Voltage 4: -12 V

Current 4: 4 A

Rack Height: 6 U

Rack Width: 8 HP

Depth: 171.93 mm

## ADDITIONAL PRODUCT DETAILS

---

Pluggable 19" Power Supply with P47 connector, for CompactPCI applications.

## CERTIFICATIONS

---





### North America

All locations

+1.763.422.2661

Chat with us:

[schroff.nvent.com](https://schroff.nvent.com)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[schroff.nvent.com](https://schroff.nvent.com)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[schroff.nvent.com](https://schroff.nvent.com)

### Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[schroff.nvent.com](https://schroff.nvent.com)



Our powerful portfolio of brands:  
[nVent.com](https://nVent.com) **CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**

© 2024 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.