





Front view :

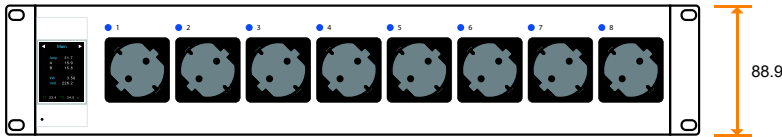

Top View :

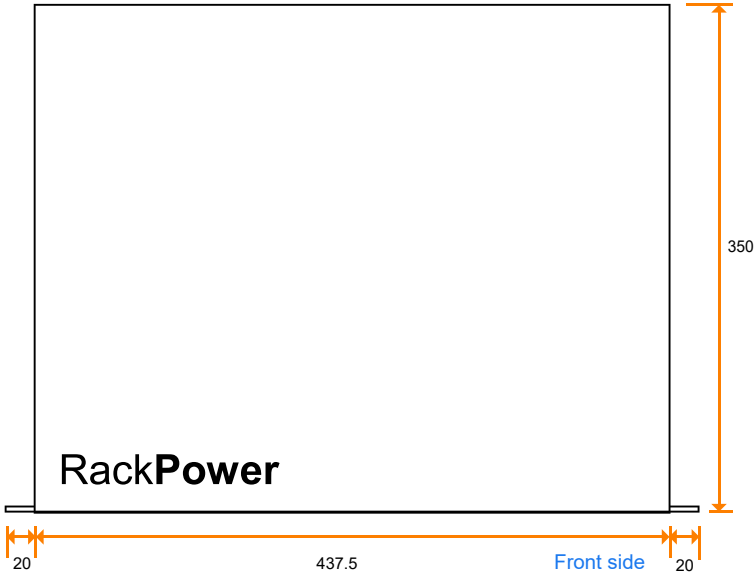

Rear view :

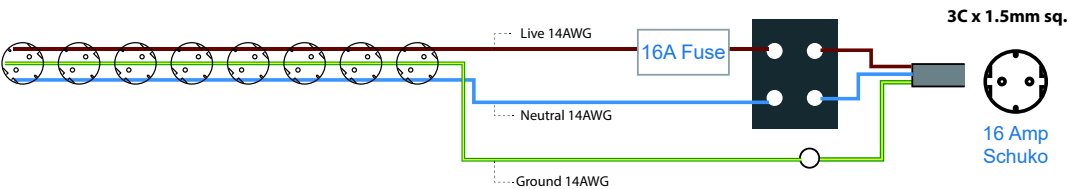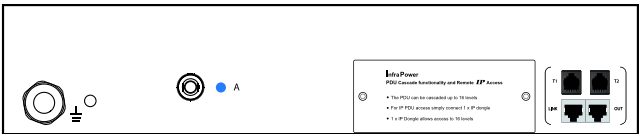

Item Number
60110-462

Single phase switched PDU + outlet measurement

Input Rating : 16A, 230V
Outlet : 16A rated Schuko x 8
Inlet : 16A Schuko plug
Cordset : 3 meter 1.5mm sq. H05V V-F cordset
Protection : 16A resettable fuse x 1
Circuit Details : Output 16A max. S C H # 1 - 8

Meter Features (WSi Switched PDU + Outlet Measurement)

Local Display : Field replaceable 2" color LCD with touchscreen
Bank Measurement : Current (A), Energy (kWh), Voltage (V) & Power factor
Outlet Measurement : Current (A), Energy (kWh)
Outlet Control : Outlet Switch ON / OFF
Accuracy : ±1% Billing-grade
IP Access : via IP dongle, one IP Access up to 16 PDU Levels
Cascade : Up to 16 PDU under single IP address via IP dongle
SNMP : V2 / V3 via IP dongle
Sensor Port x 2 : Temp. Sensor / Temp. + Humid. Sensor

EMC Compliance : CE / EMC certified
Safety Compliance : CE / LVD certified
Environment Compliance : RoHS2 & REACH
Operating Temperature : -5 to 60 °C
Storage Temperature : -25 to 65 °C
Operating Altitude : 0 to 2,000 m
Storage Altitude : 0 to 15,000 m
Humidity : 8 to 95% RH, non-condensing
Chassis Material : Steel
Chassis Color : Black
Product Dimension : 437.5 (W) x 350 (D) x 88.9 (H) mm
Net Weight : 5.27 kg
Packing Dimension : 540 (W) x 540 (D) x 150 (H) mm
PDU Gross Weight : 5.77 kg