

Item Number
60110-467

Single phase monitored + outlet measurement PDU

Input Rating : 16A, 230V
Outlet : 10A Rated C13 x 20
Inlet : 16A IEC60309 2P+E plug
Cordset : 3 meter 1.5mm sq. H05V V-F cordset
Protection : 16A resettable fuse x 1
Circuit Details : Output 16A max. C 13 # 1 - 20

Meter Features (Wi Monitored PDU + Outlet Measurement)

Local Display : Field replaceable 2.8" color LCD with touchscreen
Bank Measurement : Current (A), Energy (kWh), Voltage (V) & Power factor
Outlet Measurement : Current (A), Energy (kWh)
Accuracy : ±1% Billing-grade
IP Access : via IP dongle, one IP Access up to 16 PDU Levels
Cascade : Up to 16 PDU under single IP address via IP dongle
SNMP : V2 / V3 via IP dongle
Sensor Port x 2 : Temp. Sensor / Temp. + Humid. Sensor

EMC Compliance : CE / EMC certified
Safety Compliance : CE / LVD certified
Environment Compliance : RoHS2 & REACH

Operating Temperature : -5 to 60 °C
Storage Temperature : -25 to 65 °C
Operating Altitude : 0 to 2,000 m
Storage Altitude : 0 to 15,000 m
Humidity : 8 to 95% RH, non-condensing


Material : Steel
Color : Black

Product Dimension : 2.1 (W) x 3.1 (D) x 53.1 (H) inch
Net Weight : 12.03 lbs

Packing dimension (for 2 PDUs) : 4.3 (W) x 10.6 (D) x 70.6 (H) inch
PDU gross weight (for 2 PDUs) : 31.18 lbs

Mounting Method

VMS :

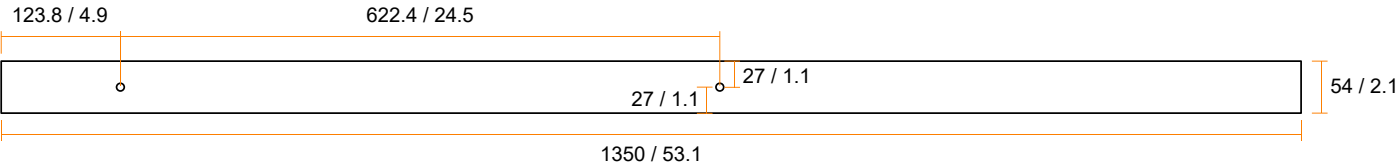

VMB :

Top feed

Bottom feed

