
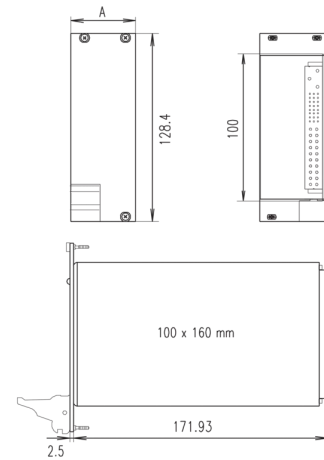


13100-142 PSU 19" FOR COMPACTPCI, DC/DC, 3 U, 8 HP

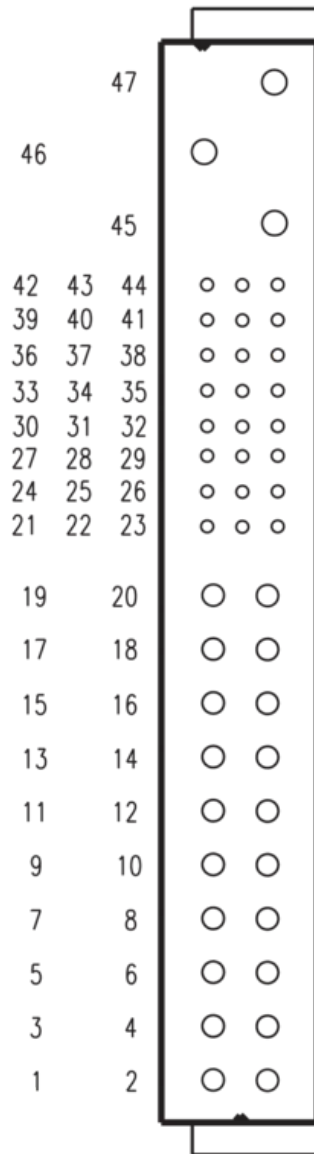

KEY FEATURES

Connector P47 and CompactPCI signalling

4 output voltages

Redundant operation with Current Share Bus (CSB), hot-swap

PRODUCT ATTRIBUTES

Product Type: Power Supply

Type: 19" DC/DC Converter

Works With: CompactPCI and VME64x

Input Voltage DC: 36 – 75 V

Power: 250 W

Number of Output Voltages: 4

Voltage 1: 5 V

Current 1: 40 A

Voltage 2: 3.3 V

Current 2: 40 A

Voltage 3: 12 V

Current 3: 5.5 A

Voltage 4: -12 V

Current 4: 2 A

Rack Height: 3 U

Rack Width: 8 HP

Depth: 171.93 mm

ADDITIONAL PRODUCT DETAILS

Pluggable 19" Power Supply with P47 connector, for CompactPCI applications.

CERTIFICATIONS





North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**

© 2024 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.