


## 13100-205 PSU 19" AC/DC FOR VMEBUS, MPS 015, 6 U

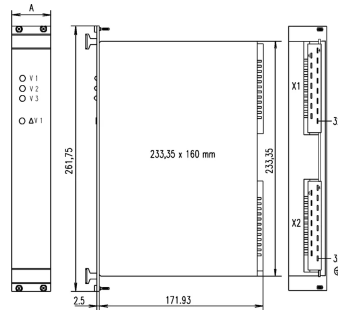

### KEY FEATURES

Wide input voltage range 90 ... 264 VAC and 130 ... 350 VDC with active power factor correction (PFC)

VMEbus signalling

3 output voltages

### PRODUCT ATTRIBUTES

Product Type: Power Supply

Type: 19" Switched-Mode

Works With: VMEbus Systems

Input Voltage AC: 90 – 264 V

Power: 150 W

Number of Output Voltages: 3

Voltage 1: 5 V

Current 1: 20 A

Voltage 2: 12 V

Current 2: 4 A

Voltage 3: -12 V

Current 3: 3 A

Rack Height: 6 U

Rack Width: 8 HP

Depth: 171.93 mm

## ADDITIONAL PRODUCT DETAILS

---

Pluggable 19" Power Supply for VMEbus applications.

Output data at TU = 0 ... 40 °C.

Output power V2 + V3 = 60 W.

Output currents (UL values in bracket): V1 = 5 V / I1 = 20 A (18 A) V2 = 12 V / I2 = 4 A (3 A) V3 = -12 V / I3 = 3 A (2 A).

## CERTIFICATIONS

---



### North America

All locations  
+1.763.422.2661  
Chat with us:  
[schroff.nvent.com](https://schroff.nvent.com)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[schroff.nvent.com](https://schroff.nvent.com)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[schroff.nvent.com](https://schroff.nvent.com)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[schroff.nvent.com](https://schroff.nvent.com)



Our powerful portfolio of brands:  
[nVent.com](https://nVent.com) **CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**

© 2024 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.