
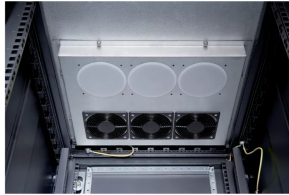


21630-782 VARISTAR CP TOP COVER WITH 6 ENERGY EFFICIENT FAN TRAY,
RAL 7021, 600W, 1200D

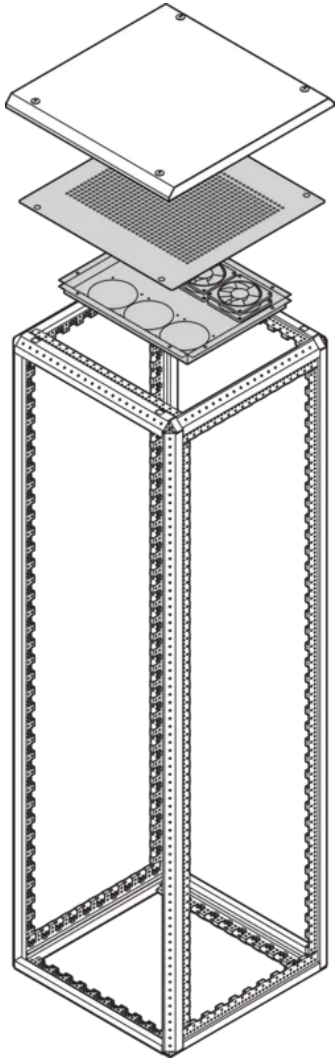

KEY FEATURES

6 axial fans fitted

Schuko/IEC 60320 C12 plug

6 power saving axial fans fitted

Wide range power input 90-260 VAC

Speed control with 2 T° sensors

Alarm over T° and fan fail (Display panel at front & relay outputs)

Remote control over Modbus RTU or Guardian

PRODUCT ATTRIBUTES

Product Type: Fan

Product Family: Varistar CP

Type: Top cover with fans

Works With: Varistar CP

Voltage DC: 24 V

Depth: 1200 mm

Color: Black Grey

Airflow: 171 m³/h

Noise Level: 42.5 dB(A)

Max Static Pressure: 68.1 Pa

Color Code: RAL 7021

Complies With: IEC 61587-1

Finish: Powder Coated

Width: 600 mm

ADDITIONAL PRODUCT DETAILS

Varistar Fan Top Cover with 3 Fans, expandable to 6 fans.

Please purchase the grounding kit separately.

North America

All locations

+1.763.422.2661

Chat with us:

schroff.nvent.com

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

schroff.nvent.com

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

schroff.nvent.com



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**

© 2024 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.