
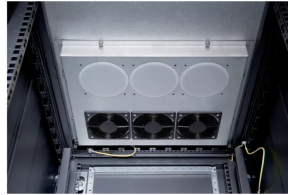


21630-796 VARISTAR CP EMC TOP COVER WITH 6 ENERGY EFFICIENT FAN TRAY, RAL 7021, 800W 600D

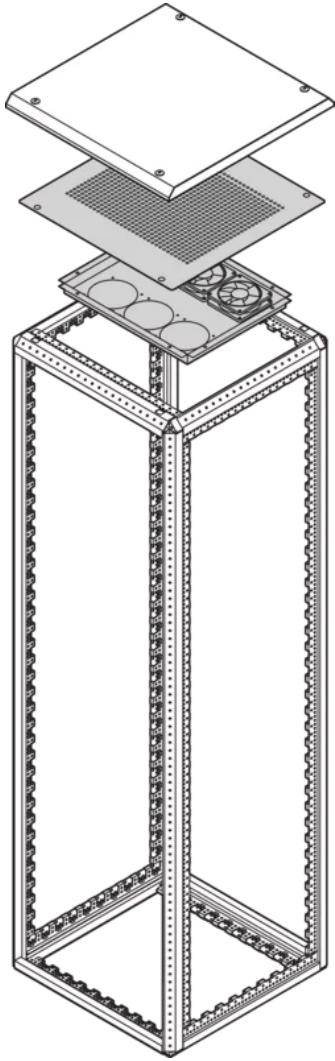

**KEY FEATURES**

6 axial fans fitted

Schuko/IEC 60320 C12 plug

6 power saving axial fans fitted

Wide range power input 90-260 VAC

Speed control with 2 T° sensors

Alarm over T° and fan fail ( Display panel at front & relay outputs)

Remote control over Modbus RTU or Guardian

## PRODUCT ATTRIBUTES

---

Product Type: Fan

Product Family: Varistar CP

Type: Top cover with fans

Works With: Varistar CP

Voltage DC: 24 V

Depth: 600 mm

Color: Black Grey

Protection Rating: IP20

Airflow: 171 m<sup>3</sup>/h

Noise Level: 42.5 dB(A)

Max Static Pressure: 68.1 Pa

Color Code: RAL 7021

Complies With: IEC 61587-1

Finish: Powder Coated

Width: 800 mm

## ADDITIONAL PRODUCT DETAILS

---

Varistar Fan Top Cover with 3 Fans, expandable to 6 fans.

Please purchase the grounding kit separately.

### North America

All locations

+1.763.422.2661

Chat with us:

[schroff.nvent.com](https://schroff.nvent.com)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[schroff.nvent.com](https://schroff.nvent.com)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[schroff.nvent.com](https://schroff.nvent.com)

### Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[schroff.nvent.com](https://schroff.nvent.com)



Our powerful portfolio of brands:  
[nVent.com](https://nVent.com) **CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**

© 2024 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.