



# Mounting and Installation

CONNECT AND PROTECT


## SERIES 223-255

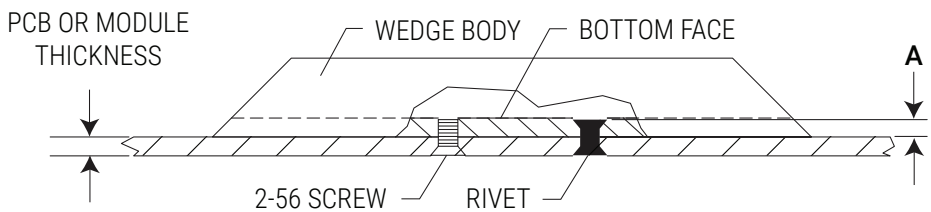

## SERIES 260-267

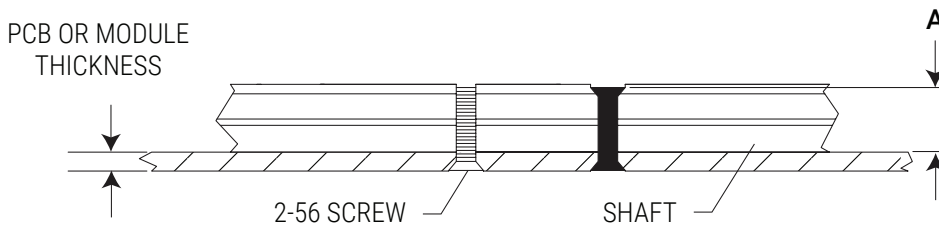



## SERIES 280/281

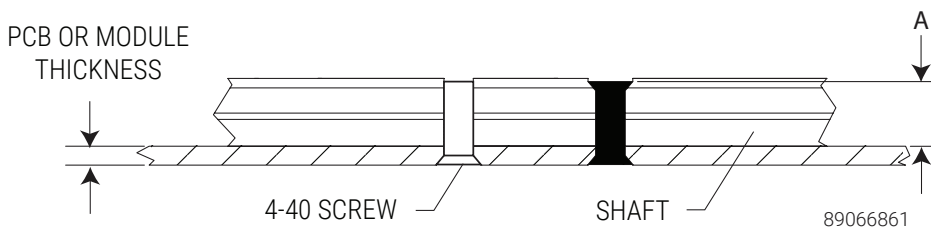

Series	"A" Recommended
223	1.143 (0.045)
224	1.524 (0.060)
225	1.143 (0.045)
E225	1.143 (0.045)
L225	1.143 (0.045)
226	1.270 (0.050)
227	2.667 (0.105)
228	2.667 (0.105)
230	0.889 (0.035)
231	0.889 (0.035)
235	1.270 (0.050)
236	1.270 (0.050)
240	0.762 (0.030)
245	1.143 (0.045)
250	1.905 (0.075)
255	1.905 (0.075)
260	4.953 (0.195)
260HTS	1.778 (0.070)
261	4.953 (0.195)
L260	4.953 (0.195)
LE260	4.953 (0.195)
263	4.953 (0.195)
264	4.953 (0.195)
265	4.953 (0.195)
265HTS	1.270 (0.050)
266	4.953 (0.195)
267	3.810 (0.150)
280	7.366 (0.290)
280HTS	2.718 (0.107)
281	8.382 (0.330)

Screw Length and Head Style depend on details of the application. In general, the screw should not extend beyond the bottom face of the wedge body or top edge of the shaft.

## SUGGESTED RIVET DIMENSIONS

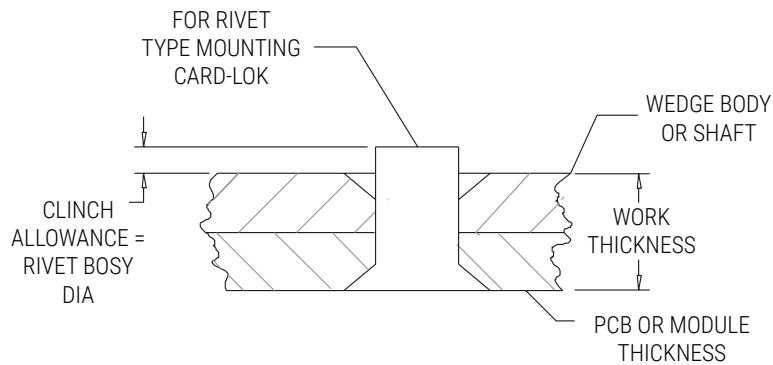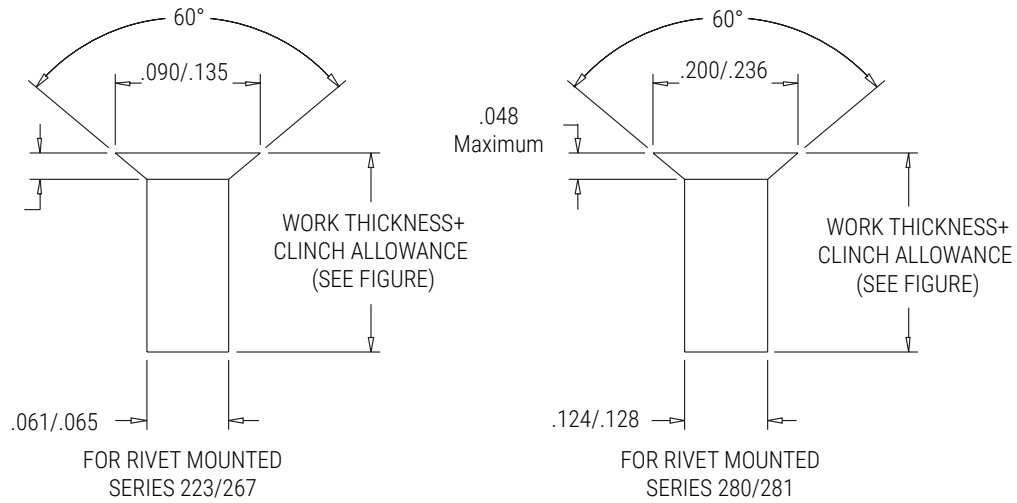

89066862

### nVent SCHROFF, Inc.

7328 Trade Street  
San Diego, CA 92121 USA  
+1 800-525-4682



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**